

Technical data sheet

Zinc-nickel coated steel sleeve, with thread

Item number: 2046558



Accessory part: coupling with thread according to EN 60423 to connect electrical installation pipes and 90° bends.



St	Steel
DN	Zinc / nickel coated

Master data

Item number	2046558
Type	SVM40W DN
Description 1	Conduit threaded coupler
Description 2	with thread
Manufacturer	OBO
Dimension	M40x1,5
Material	Steel
Surface	Zinc / nickel coated
Surface standard	
Smallest sales unit	25
Unit of quantity	Piece
Weight	11.4 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,3596 kg COe / 1 Piece


Technical data sheet

Zinc-nickel coated steel sleeve, with thread

Item number: 2046558



Dimensions

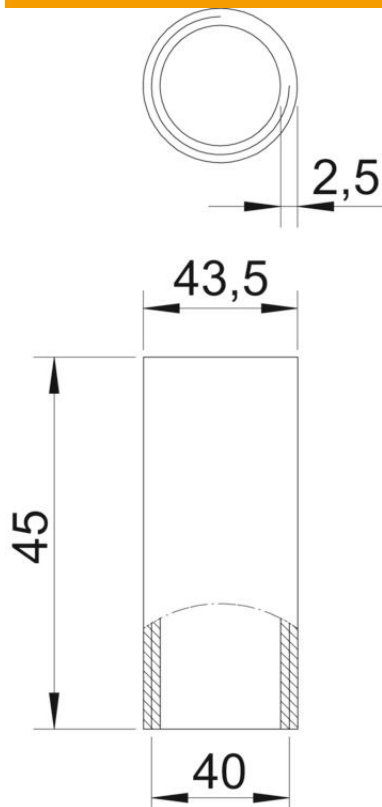

Length	45 mm
Dimension D	43.5 mm
Dimension d	40 mm
Dimension L	45 mm
Dimension m (mm)	M40
Dimension t	2.5 mm

Technical data

Version for for pipe diameter	Thread
Thread	40 mm
Size	M40x1,5
Halogen-free	40
With inspection opening and lid	no
Brushed surface	no
Polished surface	no
Permitted temperature range, max.	400 °C
Permitted temperature range, min.	-45 °C
Two-part	no