

# Technical data sheet

## Zinc-nickel coated steel sleeve, with thread

Item number: 2046560



Accessory part: coupling with thread according to EN 60423 to connect electrical installation pipes and 90° bends.



|           |                      |
|-----------|----------------------|
| <b>St</b> | Steel                |
| <b>DN</b> | Zinc / nickel coated |

### Master data

|                                   |                          |
|-----------------------------------|--------------------------|
| Item number                       | 2046560                  |
| Type                              | SVM63W DN                |
| Description 1                     | Conduit threaded coupler |
| Description 2                     | with thread              |
| Manufacturer                      | OBO                      |
| Dimension                         | M63x1,5                  |
| Material                          | Steel                    |
| Surface                           | Zinc / nickel coated     |
| Surface standard                  |                          |
| Smallest sales unit               | 5                        |
| Unit of quantity                  | Piece                    |
| Weight                            | 30.7 kg                  |
| Weight unit                       | kg/100 pc.               |
| CO Footprint (GWP) Cradle-to-Gate | 0,8907 kg COe / 1 Piece  |


# Technical data sheet

## Zinc-nickel coated steel sleeve, with thread

Item number: 2046560



### Dimensions

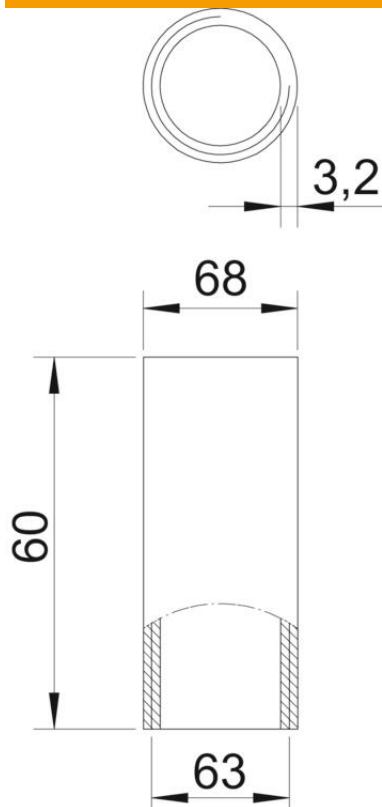

|                  |        |
|------------------|--------|
| Length           | 60 mm  |
| Dimension D      | 68 mm  |
| Dimension d      | 63 mm  |
| Dimension L      | 60 mm  |
| Dimension m (mm) | M63    |
| Dimension t      | 3.2 mm |

### Technical data

|                                      |         |
|--------------------------------------|---------|
| Version for<br>for pipe diameter     | Thread  |
| Thread                               | 63 mm   |
| Size                                 | M63x1,5 |
| Halogen-free                         | 63      |
| With inspection opening and lid      | no      |
| Brushed surface                      | no      |
| Polished surface                     | no      |
| Permitted temperature range,<br>max. | 400 °C  |
| Permitted temperature range,<br>min. | -45 °C  |
| Two-part                             | no      |