


# Technical data sheet

Threaded rod A4 1000

Item number: 3141502

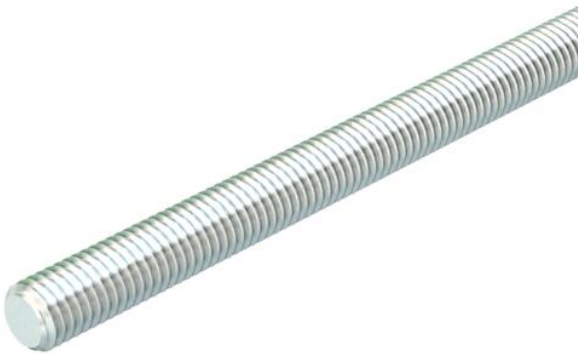

Threaded rod to DIN 976.



- A4 Stainless steel
- 2B Bright, treated

| Master data         |                 |
|---------------------|-----------------|
| Item number         | 3141502         |
| Description 1       | Threaded rod    |
| Manufacturer        | OBO             |
| Dimension           | M10x1000mm      |
| Material            | Stainless steel |
| Surface             | Bright, treated |
| Surface standard    |                 |
| Smallest sales unit | 1               |
| Unit of quantity    | Piece           |
| Weight              | 49 kg           |
| Weight unit         | kg/100 pc.      |


# Technical data sheet

Threaded rod A4 1000

Item number: 3141502



## Dimensions

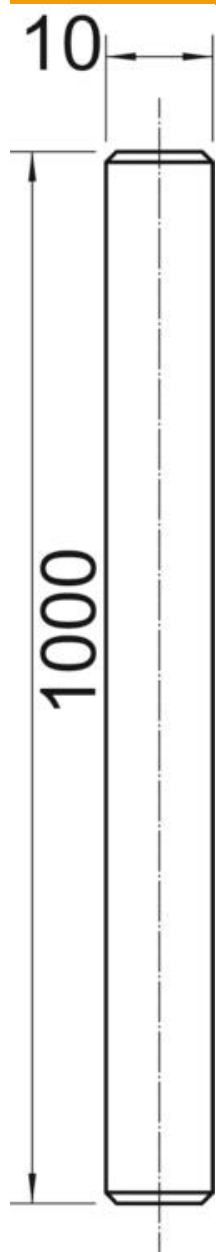

|             |          |
|-------------|----------|
| Length      | 1,000 mm |
| Dimension d | 10 mm    |
| Dimension L | 1,000 mm |

# Technical data sheet

Threaded rod A4 1000

Item number: 3141502



## Technical data

|               |         |
|---------------|---------|
| Breaking load | 62.8 kN |
| Thread        | M10     |
| Thread metric | 10      |
| Left thread   | no      |