


# Technical data sheet

## Threaded rod A2 2000

Item number: 3141339

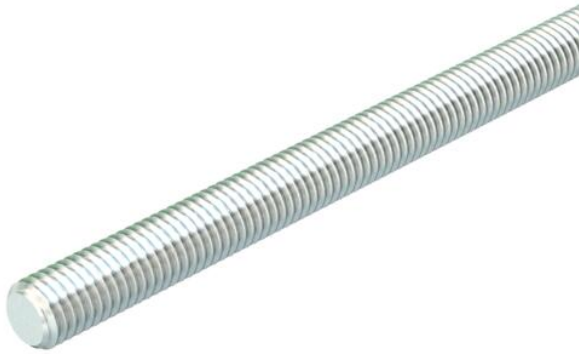

Threaded rod to DIN 976.

|           |                 |
|-----------|-----------------|
| <b>A2</b> | Stainless steel |
| <b>2B</b> | Bright, treated |

### Master data

|                     |                 |
|---------------------|-----------------|
| Item number         | 3141339         |
| Type                | TR M10 2M A2    |
| Description 1       | Threaded rod    |
| Manufacturer        | OBO             |
| Dimension           | M10x2000mm      |
| Material            | Stainless steel |
| Surface             | Bright, treated |
| Surface standard    |                 |
| Smallest sales unit | 10              |
| Unit of quantity    | Piece           |
| Weight              | 98 kg           |
| Weight unit         | kg/100 pc.      |


# Technical data sheet

## Threaded rod A2 2000

Item number: 3141339



### Dimensions

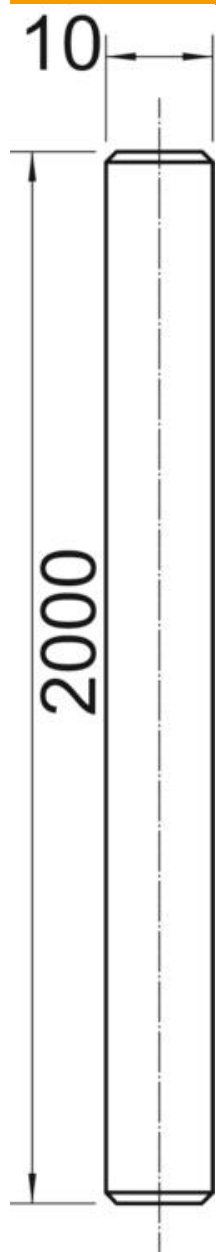

|             |          |
|-------------|----------|
| Length      | 2,000 mm |
| Dimension d | 10 mm    |
| Dimension L | 2,000 mm |

# Technical data sheet

Threaded rod A2 2000

Item number: 3141339



## Technical data

|               |          |
|---------------|----------|
| Breaking load | 54.95 kN |
| Thread        | M10      |
| Thread metric | 10       |
| Left thread   | no       |