


Technical data sheet

Barrier strip, Z-shaped 110 FS

Item number: 6062391

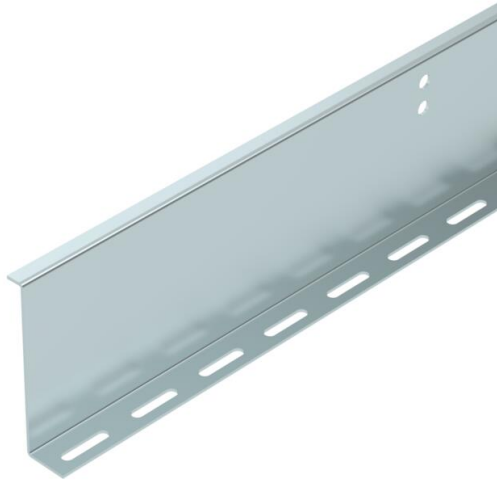

Barrier strip for the BKRS walkable cable tray system. Fastening with truss-head bolts M6 x 12 in the base perforation.
For widths of 200 mm or more, a barrier strip with a maximum compartment size of 220 mm should be used.
For widths of 500 mm or more, two barrier strips with a maximum compartment size of 220 mm should be used.



St	Steel
FS	Strip galvanized

Master data

Item number	6062391
Description 1	Barrier strip
Description 2	Z type, for BKS
Manufacturer	OBO
Dimension	110x2x3000
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	3
Unit of quantity	Metre
Weight	210.433 kg
Weight unit	kg/100 m


Technical data sheet

Barrier strip, Z-shaped 110 FS

Item number: 6062391



Dimensions

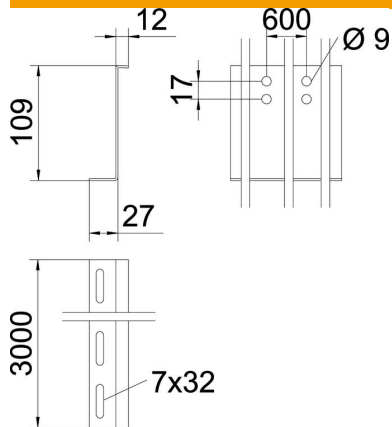

Length	3,000 mm
Length	10 ft
Width	34 mm
Height	109 mm
Height	4 in
Plate thickness	2 mm
Dimension H (Inch)	4 in
Dimension H	110 mm
Dimension L	10 ft
Dimension L	3,000 mm

Technical data

Version for	Miscellaneous
Fastening type	Screw-on
Fastening perforation (ETIM)	yes
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Rustproof steel, pickled	no