

Technical data sheet

T100 junction box, without Wieland socket, 3–5-pin

Item number: 2007840



Junction box for 4 Wieland sockets, 3-5-pin, for the connection of cables indoors and in protected outdoor areas. Rectangular design with knock-out entries to the sides and knock-out entries in the bottom. Suitable for wall and ceiling mounting and on mounting panels. With the option of fastening inside and to mount via the corner domes. Cover with quick lock, sealable. Made from halogen-free and UV-resistant materials.

Junction box according to DIN EN 60670. Flame-resistant to DIN EN 60695/2/11, test temperature 650 °C.
Clear internal dimensions: 136x102x57 mm



| Master data | |
|------------------------------------|--------------------------------|
| Item number | 2007840 |
| Type | T 100 WB5 |
| Description 1 | Junction box |
| Description 2 | for 5 Wieland sockets,3-5-pole |
| Manufacturer | OBO |
| Dimension | 150x116x67 |
| Colour | Light grey; RAL 7035 |
| Material | Polypropylene |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 15.6 kg |
| Weight unit | kg/100 pc. |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,7435 kg COe / 1 Piece |


Technical data sheet

T100 junction box, without Wieland socket, 3–5-pin

Item number: 2007840



Dimensions

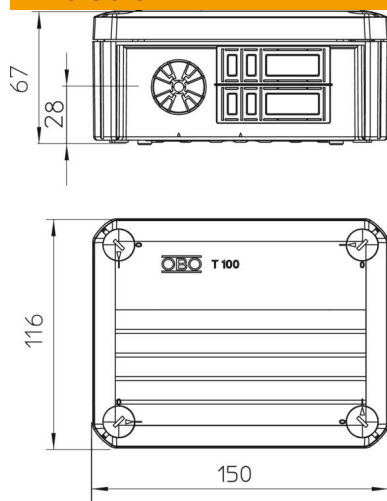

| | |
|--------|--------|
| Length | 150 mm |
| Width | 116 mm |
| Height | 67 mm |

Technical data

| | |
|-----------------------------------|--|
| Expandable | yes |
| No. of entries | 4 |
| Type of insertion | Strain relief entries for direct penetrations for cable diameters of 7–21 mm |
| Type of housing penetration | Pre-marking |
| Measured insulation voltage V_i | 500 V |
| Equipment | Miscellaneous |
| Cover | Not transparent |
| Cover fastening | Screwed |
| Entry from rear | yes |
| Entries | 4 |
| Explosion-tested version | no |
| Flame-resistant | acc. to VDE 0471/DIN 695 Part 2-1, test temperature 650°C |
| Shape | Rectangular |
| Maintain electrical functions | Without |
| For Ex zone | Without |
| For Ex zone gas | Without |
| For Ex zone dust | Without |
| Halogen-free | yes |
| Clear internal dimensions | 136x102x57 mm |
| With screening | no |
| with lid | yes |
| Mounting type | Wall/ceiling mounting |
| Nominal cross-section, min. | 2.5 mm ² |
| Nominal voltage | 500 V |
| Sealable | yes |
| Protection rating | IP20 |
| Permitted temperature range, max. | 60 °C |
| Permitted temperature range, min. | -5 °C |

Technical data sheet

T100 junction box, without Wieland socket, 3–5-pin

Item number: 2007840



Technical data

| | |
|-----------------|----|
| Transparent lid | no |
| Weatherproof | no |