

# Technical data sheet

## UP Flush-mounted electronics box 46, rectangular, with clamping area to the side

Item number: 2003725



Flush-mounted electronics box, with side clamping space, rectangular shape, for use in masonry with an installation depth of at least 50 mm.

- Connector with bayonet lock, couplable on both sides
  - 10 combination pipe entries of Ø 20 and 25 mm
  - 2 entries up to Ø 20 mm in the base
  - 4 entries for flat cables/ribbon cables
  - 4 x 3 screw domes
- Tested according to DIN EN 60670-1, DIN EN 60670-22 and DIN 49073-1.



**PP** Polypropylene

### Master data

Item number	2003725
Type	UE 46
Description 1	UP Flush-mount. electronic box
Description 2	with lateral terminal area
Available from	01.10.2021
Manufacturer	OBO
Dimension	Ø60xH50x114
Colour	Jet black
Material	Polypropylene
Smallest sales unit	10
Unit of quantity	Piece
Weight	4.3 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,1666 kg COe / 1 Piece


# Technical data sheet

UP Flush-mounted electronics box 46, rectangular, with  
clamping area to the side

Item number: 2003725



## Dimensions

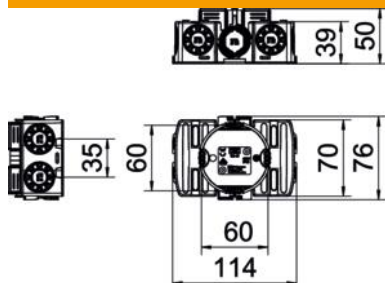

Length	114 mm
Width	76 mm
Height	50 mm

## Technical data

No. of entries	16
Type of insertion	NYM cables, data cables and corrugated pipes
Type of housing penetration	Break-out opening
Version for	Single
Type	Electrics socket
Device fixing	Screws ,
Cover	Without
Cover fastening	Screws ,
Entry from rear	yes
Flame-resistant	acc. to VDE 0471/IEC 60695-2-11, test temperature 650°C
Shape	Rectangular
for pipe diameter	20/25 mm
Accessory screw clearance	60 mm
Halogen-free	yes
Combination entries Ø 20 / 25 mm	10
With nail strap	no
With bolts	yes
Nominal cross-section, max.	2.5 mm <sup>2</sup>
Nominal cross-section, min.	1.5 mm <sup>2</sup>
Pipe entries Ø 20 mm	2
Impact-resistant	yes
Protection rating	IP30
Airtight	no
Rated voltage	400 V