

Technical data sheet

UP Flush-mounted electronics box 66, additional clamping space

Item number: 2003726



Flush-mounted electronics box, with additional terminal area, for use in masonry with an installation depth of at least 66 mm.

- With 4 couplable connectors with bayonet lock
 - 6 combination pipe entries of Ø 20 and 25 mm
 - 8 entries up to Ø 20 mm
 - 6 entries up to Ø 14 mm
 - 2 entries up to Ø 20 mm in the base
 - Partition for different voltages, with break-out openings
 - 4 x 3 screw domes
- Tested according to DIN EN 60670-1, DIN EN 60670-22 and DIN 49073-1.



PP Polypropylene

Master data

Item number	2003726
Type	UE 66
Description 1	UP Flush-mount. electronic box
Description 2	with device screws
Available from	01.10.2021
Manufacturer	OBO
Dimension	Ø60xH66x148
Colour	Jet black
Material	Polypropylene
Smallest sales unit	10
Unit of quantity	Piece
Weight	6.15 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,2232 kg COe / 1 Piece


Technical data sheet

UP Flush-mounted electronics box 66, additional clamping space

Item number: 2003726



Dimensions

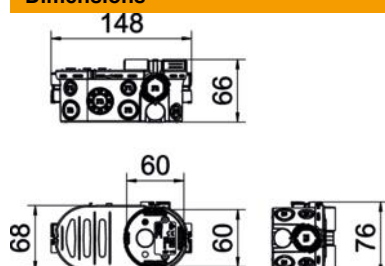

Length	148 mm
Width	76 mm
Height	66 mm

Technical data

No. of entries	22
Type of insertion	NYM cables, data cables and corrugated pipes
Type of housing penetration	Break-out opening
Version for	Single
Type	Electrics socket
Device fixing	Screws ,
Cover	Without
Cover fastening	Screws ,
Entry from rear	yes
Flame-resistant	acc. to VDE 0471/IEC 60695-2-11, test temperature 650°C
Shape	Oval
for pipe diameter	20/25 mm
Halogen-free	yes
Combination entries Ø 20 / 25 mm	6
Max. Conductor cross-section	2.5 mm ²
With nail strap	no
With bolts	yes
Nominal cross-section, max.	2.5 mm ²
Nominal cross-section, min.	1.5 mm ²
Pipe entries Ø 20 mm	10
Impact-resistant	yes
Protection rating	IP30
Airtight	no
Rated voltage	400 V