

# Technical data sheet

## UP Flush-mounted device connection box 66, with device screws, airtight

Item number: 2003709



Flush-mounted device box, with airtight membrane entries, for use in masonry with an installation depth of at least 66 mm.

- 4 x 3 screw domes
  - 2 pre-mounted device screws
  - Connector with bayonet lock, couplable on both sides
  - 4 combination pipe entries of Ø 20 and 25 mm
  - 2 entries up to Ø 20 mm
  - 6 entries up to Ø 12 mm
  - 2 entries up to Ø 12 mm in the base
- Tested according to DIN EN 60670-1, DIN EN 60670-22 and DIN 49073-1.



PP/  
TPE

Polypropylene/thermoplastic elastomer

### Master data

Item number	2003709
Type	UG 66-GS-L
Description 1	UP Flush-mounted device box
Description 2	with device screws, airtight
Available from	01.10.2021
Manufacturer	OBO
Dimension	Ø60mm, H66mm
Colour	deep black / blue grey
Material	Polypropylen / Thermoplastisches Elastomer
Smallest sales unit	25
Unit of quantity	Piece
Weight	2.63 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,1115 kg COe / 1 Piece


# Technical data sheet

UP Flush-mounted device connection box 66, with device screws, airtight

Item number: 2003709



## Dimensions

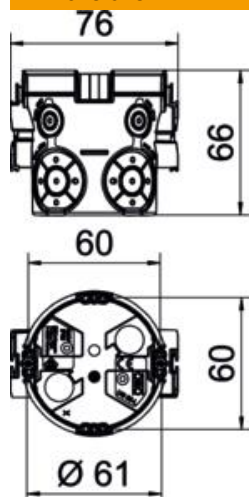

Height	66 mm
--------	-------

## Technical data

No. of entries	14
Type of insertion	NYM cables, data cables and corrugated pipes
Type of housing penetration	Insertion membrane
Version for	Single
Type	Device connection box
Device fixing	Screws or spreading claws
Cover	Without
Cover fastening	Screws ,
Entry from rear	yes
Flame-resistant	acc. to VDE 0471/IEC 60695-2-11, test temperature 650°C
Shape	Round
for pipe diameter	20/25 mm
Halogen-free	yes
Combination entries Ø 20 / 25 mm	4
With nail strap	no
With bolts	yes
Nominal cross-section, max.	2.5 mm <sup>2</sup>
Nominal cross-section, min.	1.5 mm <sup>2</sup>
Pipe entries Ø 20 mm	2
Impact-resistant	yes
Protection rating	IP30
Airtight	yes
Rated voltage	400 V