

Technical data sheet

UP Flush-mounted device connection box 66

Item number: 2003712



Flush-mounted device box, for use in masonry with an installation depth of at least 66 mm.

- 4 x 3 screw domes
 - Connection nozzle with bayonet lock, couplable on both sides
 - 6 combination pipe entries up to Ø 20 and 25 mm
 - 4 entries up to Ø 20 mm
 - 2 entries up to Ø 14 mm
 - 1 entry up to Ø 20 mm in the base
- Tested according to DIN EN 60670-1, DIN EN 60670-22 and DIN 49073-1.



Master data

Item number	2003712
Type	UG 66-LKG
Description 1	UP Flush-mounted device box
Description 2	Bulk pack, 250 pieces
Manufacturer	OBO
Dimension	Ø60mm, H66mm
Smallest sales unit	250
Unit of quantity	Piece
Weight	2.39 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0848 kg COe / 1 Piece


Technical data sheet

UP Flush-mounted device connection box 66

Item number: 2003712



Dimensions

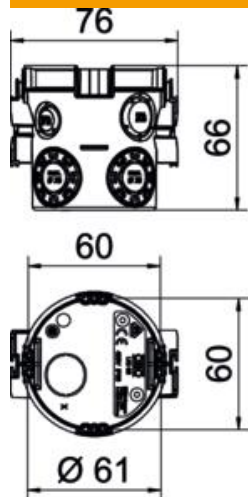

Height	66 mm
--------	-------

Technical data

No. of entries	11
Type of insertion	NYM cables, data cables and corrugated pipes
Type of housing penetration	Break-out opening
Version for	Single
Type	Device connection box
Device fixing	Screws or spreading claws
Cover	Without
Cover fastening	Screws ,
Entry from rear	yes
Flame-resistant	acc. to VDE 0471/IEC 60695-2-11, test temperature 650°C
Shape	Round
for pipe diameter	20/25 mm
Halogen-free	yes
Combination entries Ø 20 / 25 mm	6
With nail strap	no
With bolts	no
Mounting type	Concealed
Nominal cross-section, max.	2.5 mm²
Nominal cross-section, min.	1.5 mm²
Pipe entries Ø 20 mm	3
Impact-resistant	yes
Protection rating	IP30
Airtight	no
Rated voltage	400 V