

# Technical data sheet

Underfloor outlet for raised floor mounting, RF plate thickness to 60 mm

Item number: 7408582



For the installation of an accessory or the setup of a Telitank in raised floors with a plate thickness of up to 60 mm.



Die-cast zinc

## Master data


Item number	7408582
Type	US80 DB 38
Description 1	Underfloor outlet
Description 2	for RF thicknesses <60 mm
Manufacturer	OBO
Material	Die-cast zinc
Smallest sales unit	1
Unit of quantity	Piece
Weight	54.2 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,4809 kg COe / 1 Piece

# Technical data sheet

Underfloor outlet for raised floor mounting, RF plate thickness to 60 mm  
Item number: 7408582



## Dimensions

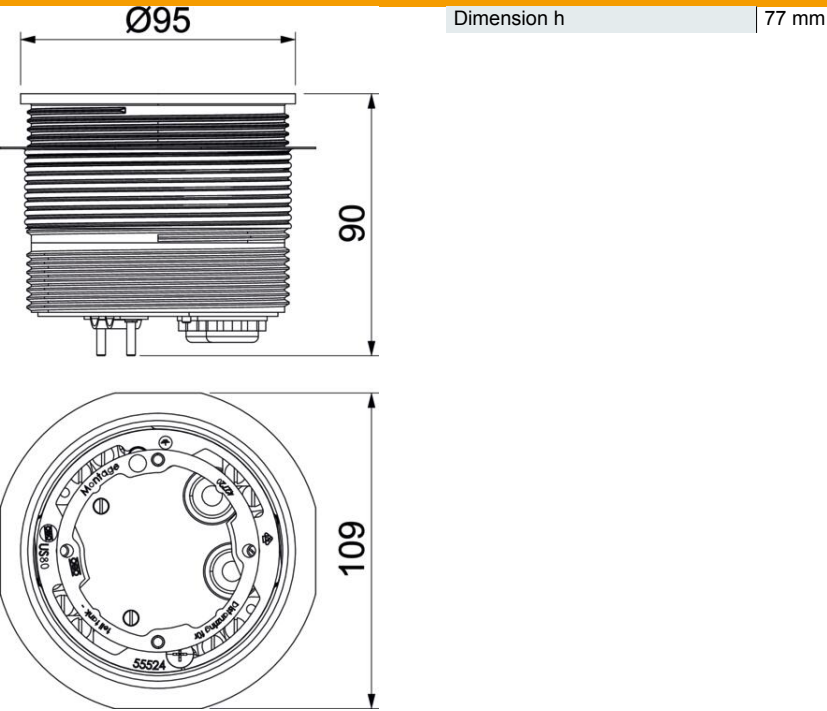

## Technical data

Expansion option	For raised tank
Cover version	Round
Seal installation option	no
For pipe connection	no