

Technical data sheet

US 3 support FS

Item number: 6342338



U support in fixed lengths. Dimensions 30 x 50 mm.
For bracket widths of 400 mm or more, or if the bracket is mounted at the end of a suspended support, we recommend the use of the spacer, type DSK 25.



St	Steel
FS	Strip galvanized

Master data

Item number	6342338
Description 1	U support
Description 2	3-sided perforated
Manufacturer	OBO
Dimension	50x30x2000
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	266 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	7,5068 kg COe / 1 Piece


Technical data sheet

US 3 support FS

Item number: 6342338



Dimensions

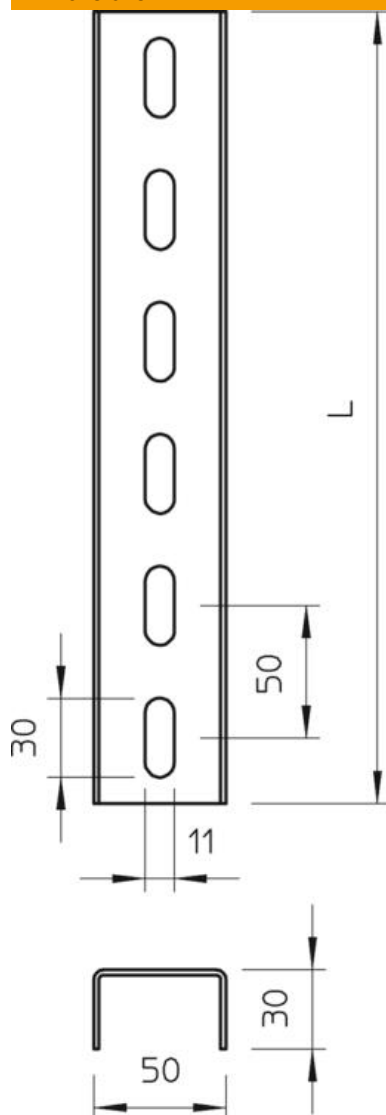

Dimension	30 x 50 x 2,0
Length	2,000 mm
Width	50 mm
Height	30 mm
Dimension L	2,000 mm

Technical data sheet

US 3 support FS

Item number: 6342338



Technical data

Breakable	no
Type of perforation	3 sides perforated
Version for	Single profile
Maintain electrical functions	yes
Hole width	11 mm
Material thickness	2 mm
With toothing	no
Profile shape	U profile
Slot width	30 mm
Static value A	1.42 cm ²
Static value Iy	1.52 cm
Static value Iz	5.72 cm
Static value Wy	0.7 cm ²
Static value Wz	2.29 cm ²