

Technical data sheet

US 5 support FT

Item number: 6340962



U support in fixed lengths. Dimensions 50 x 50 mm.

For bracket widths of 400 mm or more, or if the bracket is mounted at the end of a suspended support, we recommend the use of the spacer, type DSK 45.



St

Steel

FT

Hot-dip galvanised

Master data

Item number	6340962
Description 1	U support
Description 2	3-sided perforated
Manufacturer	OBO
Dimension	50x50x1000
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	265 kg
Weight unit	kg/100 pc.


Technical data sheet

US 5 support FT

Item number: 6340962



Dimensions

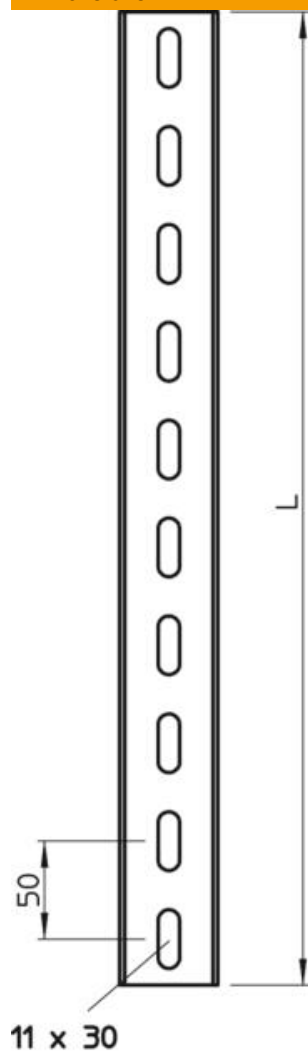

Dimension	50 x 50 x 2,5
Length	1,000 mm
Width	50 mm
Height	50 mm
Dimension L	1,000 mm

Technical data sheet

US 5 support FT

Item number: 6340962



Technical data

Breakable	no
Type of perforation	3 sides perforated
Version for	Single profile
EPD article	yes
Maintain electrical functions	yes
Material thickness	2.5 mm
With tothing	no
Profile shape	U profile
Slot width	45 mm
Static value A	2.74 cm ²
Static value Iy	8.32 cm
Static value Iz	12.53 cm
Static value Wy	2.61 cm ²
Static value Wz	5.01 cm ²