

# Technical data sheet

## US 7 support FT

Item number: 6340199



U support in fixed lengths. Dimensions 70 x 50 mm.  
For bracket widths of 400 mm or more, or if the bracket is mounted at the end of a suspended support, we recommend the use of the spacer, type DSK 61.



St

Steel

FT

Hot-dip galvanised

### Master data

|                                    |                           |
|------------------------------------|---------------------------|
| Item number                        | 6340199                   |
| Type                               | US 7 110 FT               |
| Description 1                      | U support                 |
| Description 2                      | 3-sided perforated        |
| Manufacturer                       | OBO                       |
| Dimension                          | 70x50x1100                |
| Colour                             | zinc                      |
| Material                           | Steel                     |
| Surface                            | Hot-dip galvanised        |
| Surface standard                   | DIN EN ISO 1461           |
| Smallest sales unit                | 1                         |
| Unit of quantity                   | Piece                     |
| Weight                             | 457 kg                    |
| Weight unit                        | kg/100 pc.                |
| CO2 Footprint (GWP) Cradle-to-Gate | 11,0486 kg CO2e / 1 Piece |


# Technical data sheet

## US 7 support FT


Item number: 6340199



### Dimensions

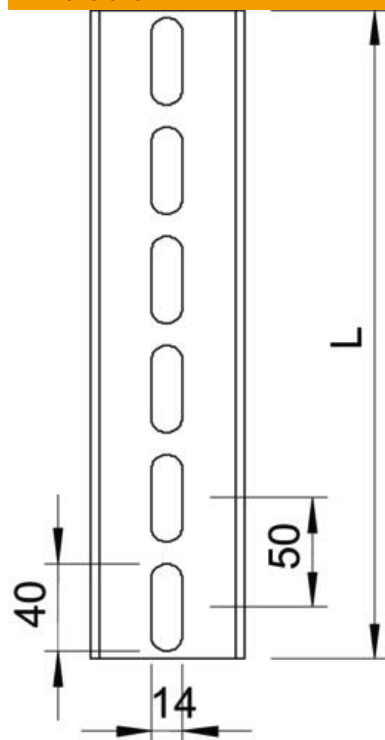

|             |             |
|-------------|-------------|
| Dimension   | 70 x 50 x 4 |
| Length      | 1,100 mm    |
| Width       | 70 mm       |
| Height      | 50 mm       |
| Dimension L | 1,100 mm    |

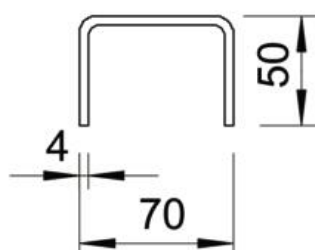

# Technical data sheet

US 7 support FT

Item number: 6340199



## Technical data

|                               |                       |
|-------------------------------|-----------------------|
| Breakable                     | no                    |
| Type of perforation           | 3 sides perforated    |
| Version for                   | Single profile        |
| EPD article                   | yes                   |
| Maintain electrical functions | yes                   |
| Hole width                    | 14 mm                 |
| Material thickness            | 4 mm                  |
| With toothing                 | no                    |
| Profile shape                 | U profile             |
| Slot width                    | 62 mm                 |
| Static value A                | 4.59 cm <sup>2</sup>  |
| Static value Iy               | 13.79 cm              |
| Static value Iz               | 36.84 cm              |
| Static value Wy               | 4.11 cm <sup>2</sup>  |
| Static value Wz               | 10.53 cm <sup>2</sup> |