

Technical data sheet

US 7 support FT

Item number: 6340253



U support in fixed lengths. Dimensions 70 x 50 mm.
For bracket widths of 400 mm or more, or if the bracket is mounted at the end of a suspended support, we recommend the use of the spacer, type DSK 61.



St Steel

FT Hot-dip galvanised

Master data

Item number	6340253
Description 1	U support
Description 2	3-sided perforated
Manufacturer	OBO
Dimension	70x50x1700
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	686 kg
Weight unit	kg/100 pc.


Technical data sheet

US 7 support FT

Item number: 6340253



Dimensions

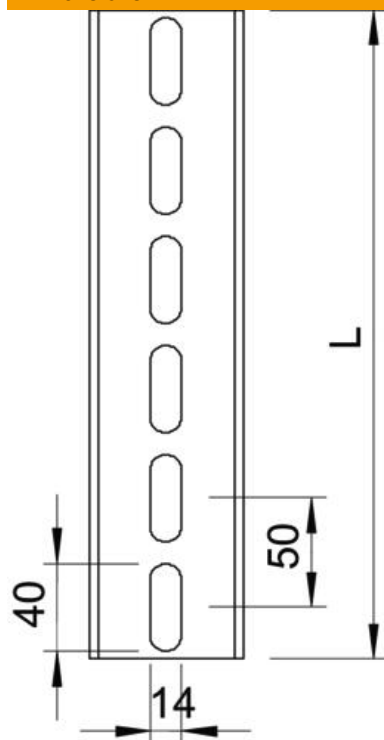

Dimension	70 x 50 x 4
Length	1,700 mm
Width	70 mm
Height	50 mm
Dimension L	1,700 mm



Technical data sheet

US 7 support FT

Item number: 6340253



Technical data

Breakable	no
Type of perforation	3 sides perforated
Version for	Single profile
EPD article	yes
Maintain electrical functions	yes
Hole width	14 mm
Material thickness	4 mm
With toothing	no
Profile shape	U profile
Slot width	62 mm
Static value A	4.59 cm ²
Static value I _y	13.79 cm
Static value I _z	36.84 cm
Static value W _y	4.11 cm ²
Static value W _z	10.53 cm ²