

# Technical data sheet

## UTC4 FI W with 2 protective contact sockets and FI/LS

Item number: 7404698



Ready-for-connection universal support Connect UTC4 with WAGO plug connector system WINSTA® MIDI. Suitable for the VL-WIN connection cables and for use in device installation units of nominal sizes R7, 9 and R9.

The ready-for-connection UTC4 FI universal support has 2 protective contact sockets protected with FI/LS. Internal wiring with 2.5 mm<sup>2</sup>. Please note the connection requirements (and also the selectivity).

Input side: Self-locking plug connector, 3-pin, type WINSTA® MIDI (connector)  
Output side: Self-locking plug connector, 3-pin, type WINSTA® MIDI (socket)

Technical features FI/LS 1P+N:

Rated current AC 16 A

Measured voltage 230 V

Tripping characteristic B

Residual current type A (pulse and alternating current sensitive)

Sensitivity 30 mA

Nominal arresting capacity 10 kA

PA Polyamide

### Master data

Item number	7404698
Type	UTC4 FI W OR2
Description 1	Universal supportConnectWINSTA
Description 2	with FI/LS, VDE, double orange
Manufacturer	OBO
Dimension	208x45x85
Material	Polyamide
Smallest sales unit	1
Unit of quantity	Piece
Weight	76.1 kg
Weight unit	kg/100 pc.



# Technical data sheet

## UTC4 FI W with 2 protective contact sockets and FI/LS

Item number: 7404698



### Dimensions

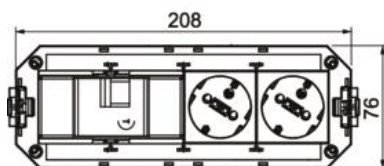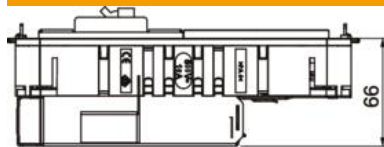

Length	218 mm
Width	76 mm
Height	85 mm

### Technical data

Number of connections	1
Number of installable devices	4
Number of strain reliefs	0
Version for	FI/LS/double pure orange
Version for	Socket shape
Installation technology	Grid M45
Line cross-section	2.5 mm <sup>2</sup>
Accessory mounting type	Lock
Socket combination	Double
Plug-in system	WINSTA® MIDI
Plug connector system, system-specific	yes
Circuit	1
Surge protection	no
Number of cable entries	2