

Technical data sheet

UTC4 W with 2+2 protective contact sockets, 2 sockets with surge protection
Item number: 7404617



The ready-for-connection UTC4 universal support possesses 2 pre-installed 33° protective contact sockets in white and 2 pre-installed 33° protective contact sockets in orange (with surge protection module, type 3, according to DIN EN 61643-11), 250 V~, 16 A. Suitable for VL connection cables and device installation units of nominal size R7, R9 and 9.

PVC connection cable with connector, 3-pin, type WINSTA® MIDI.
The ready-for-connection UTC4 universal support possesses 2 pre-installed 33° protective contact sockets in white and 2 pre-installed 33° protective contact sockets in orange (with surge protection module, type 3, according to DIN EN 61643-11), 250 V~, 16 A.

PVC connection cable with connector, 3-pin, type WINSTA® MIDI.

PA Polyamide

Master data		
Item number	7404617	
Type	UTC4 W W2OR2 Ü	
Description 1	Universal supportConnectWINSTA	
Description 2	VDE,doub.white,doub.orange,SPD	
Manufacturer	OBO	
Dimension	208x76x45	
Material	Polyamide	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	47.8 kg	
Weight unit	kg/100 pc.	

Technical data sheet

UTC4 W with 2+2 protective contact sockets, 2 sockets with surge protection


Item number: 7404617



Dimensions



Length	218 mm
Width	76 mm
Height	60 mm

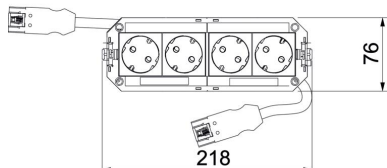

Technical data

Connection cable, halogen-free	no
Number of installable devices	4
Version for	Double pure white/double pure orange
Cable length	300 mm
Line cross-section	2.5 mm ²
Plug-in system	WINSTA® MIDI
Plug connector system, system-specific	yes
Circuit	2
System length	208 mm
Surge protection	yes