

Technical data sheet

UTC4 W with 3+1 protective contact sockets, 1 socket with surge protection

Item number: 7404622



The ready-for-connection UTC4 universal support possesses 3 pre-installed 33° protective contact sockets in white and 1 pre-installed 33° protective contact socket in orange (with surge protection module, type 3, according to DIN EN 61643-11), 250 V~, 16 A. Suitable for VL connection cables and device installation units of nominal size R7, R9 and 9.

PVC connection cable with connector, 3-pin, type WINSTA® MIDI. The ready-for-connection UTC4 universal support has 3 pre-installed 33° protective contact sockets in white and one pre-installed 33° protective contact socket in orange (with surge protection module type 3, according to DIN EN 61643-11), 250 V~ 16 A.

PVC connection cable with connector, 3-pin, type WINSTA® MIDI

PA Polyamide

Master data

| | |
|------------------------------------|-------------------------------------|
| Item number | 7404622 |
| Type | UTC4 W W3OR1 Ü |
| Description 1 | Universal supportConnectWINSTA |
| Description 2 | VDE, trip. white, sing. orange, SPD |
| Manufacturer | OBO |
| Dimension | 208x76x45 |
| Material | Polyamide |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 48.2 kg |
| Weight unit | kg/100 pc. |
| CO2 Footprint (GWP) Cradle-to-Gate | 1,2296 kg CO2e / 1 Piece |


Technical data sheet

UTC4 W with 3+1 protective contact sockets, 1 socket with surge protection

Item number: 7404622



Dimensions

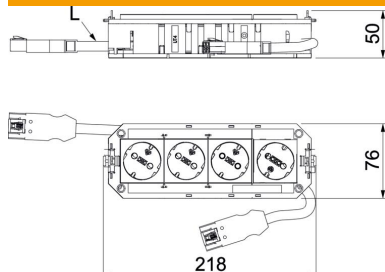

| | |
|--------|--------|
| Length | 218 mm |
| Width | 76 mm |
| Height | 60 mm |

Technical data

| | |
|--|--------------------------------------|
| Connection cable, halogen-free | no |
| Number of installable devices | 4 |
| Version for | Triple pure white/single pure orange |
| Cable length | 300 mm |
| Line cross-section | 2.5 mm ² |
| Plug-in system | WINSTA® MIDI |
| Plug connector system, system-specific | yes |
| Circuit | 1 |
| System length | 208 mm |
| Surge protection | yes |