

Technical data sheet

UVS energy distributor with fixed connection, normal circuit

Item number: 6108000



Energy distributor for heavy current technology with fixed connection, equipped and pre-wired.

Input: One 3-phase circuit via a screwless terminal block, 5-pin, for cable cross-sections of 0.5–4 mm².

Output: Six self-locking connectors, 3-pin, in black, 16 A, type GST18i (socket part: 2 x L1, 2 x L2, 2 x L3).

Internal wiring: PVC non-sheathed cable H07V-U2.5.



St Steel

Master data

Item number	6108000
Type	UVS-6S2
Description 1	Underfloor distributor
Manufacturer	OBO
Material	Steel
Smallest sales unit	1
Unit of quantity	Piece
Weight	77 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	2,2896 kg CO2e / 1 Piece


Technical data sheet

UVS energy distributor with fixed connection, normal circuit

Item number: 6108000



Dimensions

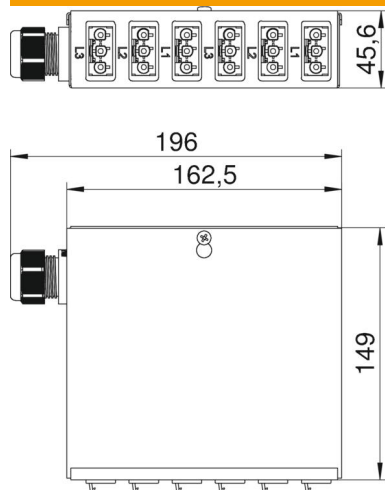

Technical data

Connection type	Terminal block
No. of outlets	6
Number of input circuits	1
Input	5-pole
Colour of the plug connector system	Black
Suitable for through wiring	no
Cross-section of the connection cable	4 mm ²
Plug connector system, system-specific	yes