


Technical data sheet

Sprung cover, 80 mm

Item number: 2004634

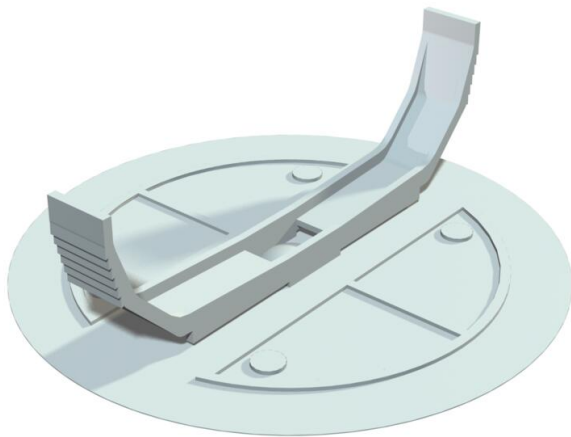

Sprung cover with centrally moulded, elastic spreading spring, for sockets with Ø 80 mm, cover edge is flush, surface is roughened.



PS Polystyrene

Master data

Item number	2004634
Type	UV 80 FD
Description 1	Sprung lid
Description 2	Concealed
Manufacturer	OBO
Dimension	Ø95mm
Colour	White
Material	Polystyrene
Smallest sales unit	25
Unit of quantity	Piece
Weight	1.5 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0415 kg COe / 1 Piece


Technical data sheet

Sprung cover, 80 mm

Item number: 2004634



Dimensions

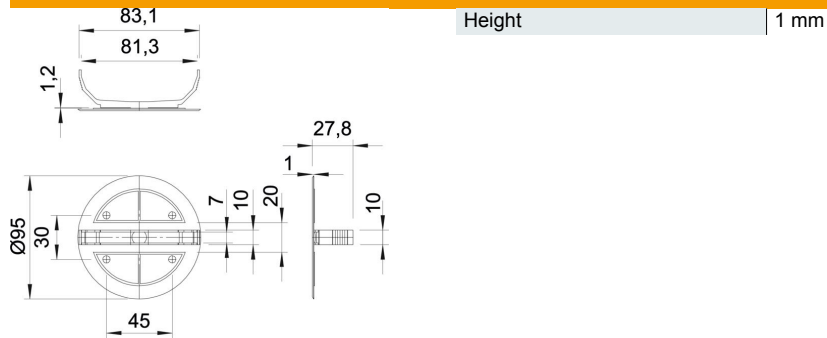

Technical data

Fastening type	Spring cover
Flame-resistant	Acc. to VDE 0471/DIN 695 Part 2-1, test temperature 750°C
Shape	Round
Halogen-free	yes
With bolts	no
Sealable	no