


Technical data sheet

Wiring trunking VF 10, flexible

Item number: 6132601

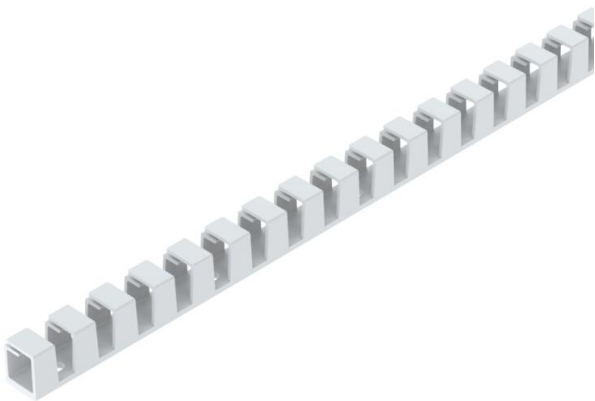

Flexible wiring trunking for horizontal and vertical routing in the switchgear cabinet.
Direct mounting on the wall via the integrated base perforation (with double-sided adhesive tape as mounting aid). Hardly inflammable and self-extinguishing after removal of a naked flame. The retainers in the trunking base can be broken out without tools.
Tested to DIN EN 50085-2-3.
Base and cover in set.

PP

Polypropylene

Master data

Item number	6132601
Type	VF 10KB rws
Description 1	Slotted cable trunking system
Description 2	VF flex 10 mm adh. 9010
Manufacturer	OBO
Colour	Pure white; RAL 9010
Material	Polypropylene
Smallest sales unit	1
Unit of quantity	Piece
Weight	1.35 kg
Weight unit	kg/100 pc.


Technical data sheet

Wiring trunking VF 10, flexible

Item number: 6132601



Dimensions

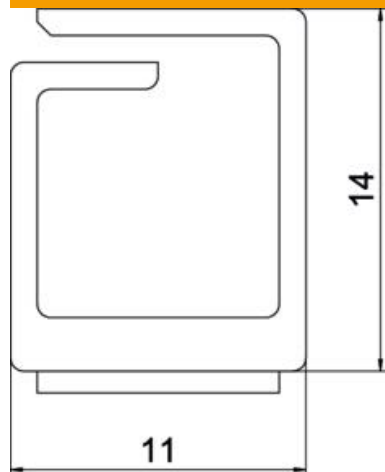

Length	500 mm
Width	11 mm
Height	14 mm

Technical data

Side wall version	Slotted
Fastening type	Self-adhesive and base perforation
Flexible	yes
Halogen-free	yes
Creepage current-resistant	yes
With cover	no
Usable cross-section	0.73 cm ²
Slot spacing	13 mm
Slot width	8 mm
Self-extinguishing	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C