


Technical data sheet

Wiring trunking VF 10, flexible

Item number: 6132600

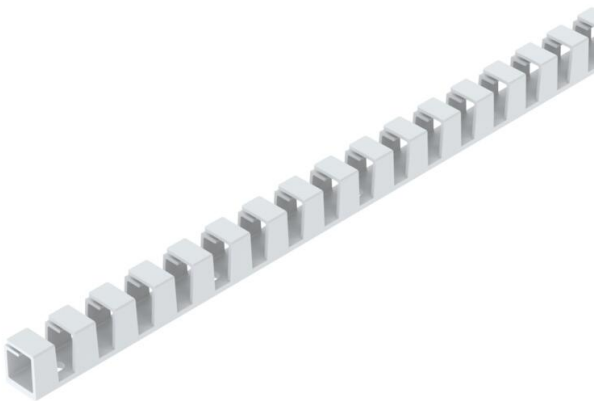

Flexible wiring trunking for horizontal and vertical routing in the switchgear cabinet.
Direct wall mounting using the integrated base perforation. Hardly inflammable and self-extinguishing after removal of a naked flame. The retainers in the duct base can be broken out without tools.
Tested to DIN EN 50085-2-3.
Base and cover in set.

PP

Polypropylene

Master data		
Item number	6132600	
Type	VF 10 rws	
Description 1	Slotted cable trunking system	
Description 2	VF flex 10 mm 9010	
Manufacturer	OBO	
Colour	Pure white; RAL 9010	
Material	Polypropylene	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	1.3 kg	
Weight unit	kg/100 pc.	


Technical data sheet

Wiring trunking VF 10, flexible

Item number: 6132600



Dimensions

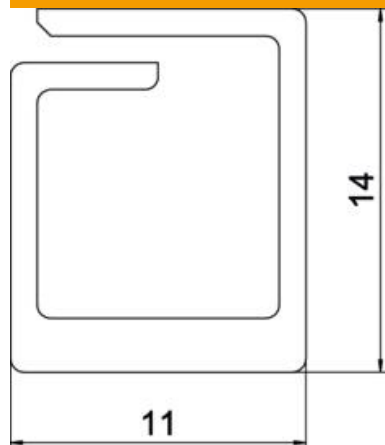

Length	500 mm
Width	11 mm
Height	14 mm

Technical data

Side wall version	Slotted
Fastening type	Base perforation
Flexible	yes
Halogen-free	yes
Creepage current-resistant	yes
With cover	no
Usable cross-section	0.73 cm ²
Slot spacing	13 mm
Slot width	8 mm
Self-extinguishing	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C