

# Technical data sheet

## Wiring trunking VF 30, flexible

Item number: 6132607



Flexible wiring trunking for horizontal and vertical routing in the switchgear cabinet.  
Direct mounting on the wall via the integrated base perforation (with double-sided adhesive tape as mounting aid). Hardly inflammable and self-extinguishing after removal of a naked flame. The retainers in the trunking base can be broken out without tools.  
Tested to DIN EN 50085-2-3.  
Base and cover in set.

**PP** Polypropylene

### Master data

|                     |                               |
|---------------------|-------------------------------|
| Item number         | 6132607                       |
| Type                | VF 30KB rws                   |
| Description 1       | Slotted cable trunking system |
| Description 2       | VF flex 30 mm adh. 9010       |
| Manufacturer        | OBO                           |
| Colour              | Pure white; RAL 9010          |
| Material            | Polypropylene                 |
| Smallest sales unit | 1                             |
| Unit of quantity    | Piece                         |
| Weight              | 5 kg                          |
| Weight unit         | kg/100 pc.                    |


# Technical data sheet

## Wiring trunking VF 30, flexible

Item number: 6132607



### Dimensions

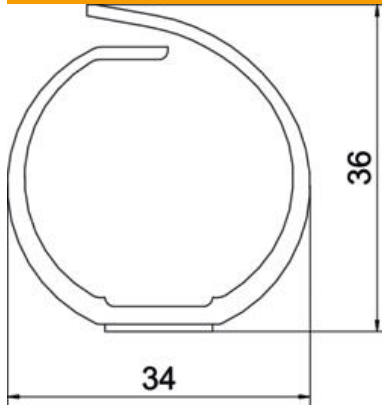

|        |        |
|--------|--------|
| Length | 500 mm |
| Width  | 34 mm  |
| Height | 36 mm  |

### Technical data

|                                   |                                    |
|-----------------------------------|------------------------------------|
| Side wall version                 | Slotted                            |
| Fastening type                    | Self-adhesive and base perforation |
| Flexible                          | yes                                |
| Halogen-free                      | yes                                |
| Creepage current-resistant        | yes                                |
| With cover                        | no                                 |
| Usable cross-section              | 8.1 cm <sup>2</sup>                |
| Slot spacing                      | 13 mm                              |
| Slot width                        | 8 mm                               |
| Self-extinguishing                | yes                                |
| Permitted temperature range, max. | 60 °C                              |
| Permitted temperature range, min. | -5 °C                              |