


Technical data sheet

VHF cover plate, for 1x surface-mounted socket, type ASD

Item number: 6109856

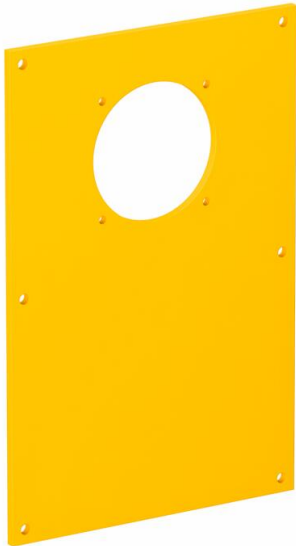

Cover plate with a Ø 45 mm opening for the installation of an extension socket (type ASD-...) with 38 mm fastening track, including 4 screws for fastening the device.



PVC Polyvinylchloride

Master data		
Item number	6109856	
Type	VHF-P12	
Description 1	Cover plate	
Description 2	1 surface-mounted socket 38x38	
Manufacturer	OBO	
Dimension	166x105mm	
Colour	Rape yellow; RAL 1021	
Material	Polyvinylchloride	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	7.4 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,2266 kg CO2e / 1 Piece	


Technical data sheet

VHF cover plate, for 1x surface-mounted socket, type ASD

Item number: 6109856



Dimensions

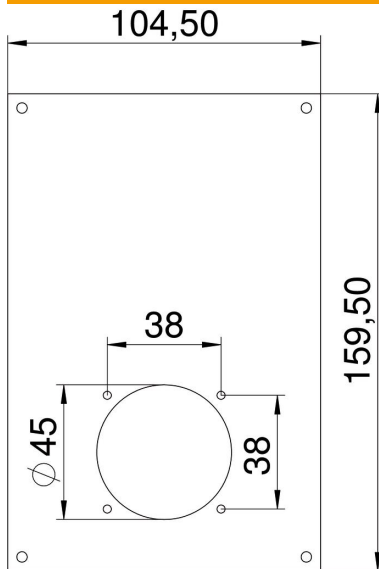

Width	104.5 mm
Height	159.5 mm

Technical data

Number of units	1
Opening shape	Round
Fastening type	Screw-on
Blanking lid	no
Halogen-free	no
Installation technology	Miscellaneous
Protection rating	IP20