


Technical data sheet

3-wire connection cable, PVC, cross-section 2.5 mm², 8 m length, black
Item number: 6108722



Connection cable 3 x 2.5 mm² in the version socket-connector, type WINSTA® MIDI.

PVC hose pipe: H05VV-F 3 x 2.5 mm²
Suitable for connection of ready-for-connection universal supports Connect UTC to an energy distributor.

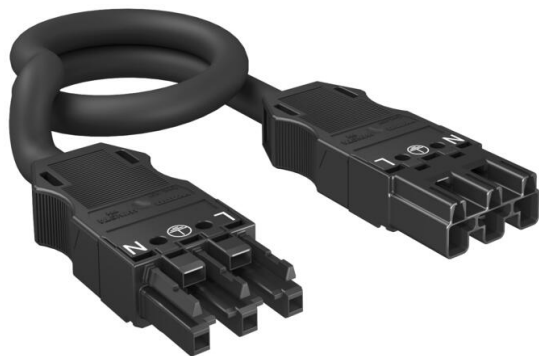

PA Polyamide

Master data		
Item number	6108722	
Type	VL-WIN 3P2.5 8SW	
Description 1	Connection cable	
Description 2	3x2,5mm ² , WINSTA	
Manufacturer	OBO	
Dimension	8000x27x15	
Colour	Black	
Material	Polyamide	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	130.17 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	5,103 kg CO2e / 1 Piece	

Dimensions	

Technical data sheet

3-wire connection cable, PVC, cross-section 2.5 mm², 8 m length, black

Item number: 6108722



Technical data

Number of poles	3
Type of terminated cable	Connection cable
Type of locking	Separate
Version, page 1	socket
Version, page 2	Connector
Rated surge voltage	4
Fire load	6.04
Colour of the coding/contact insert	Black
Halogen-free	no
Cable type	H05VV-F
Cable length	8000 mm
Jacket colour	Black
Mechanical encoding	yes
Nominal voltage	250 V
Nominal current	20 A
Pin labelling	L, N, PE
Cross-section	1.5 mm ²
Protection rating	IP20
Degree of soiling	3