

Technical data sheet

U support connector FT

Item number: 6018378



U support connector to connect US 7 supports.
Including appropriate fastening material.



St

Steel

FT

Hot-dip galvanised

Master data

Item number	6018378
Description 1	U support connector
Description 2	including truss-head bolts
Manufacturer	OBO
Dimension	190x61
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	10
Unit of quantity	Piece
Weight	112.8 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	2,101 kg COe / 1 Piece


Technical data sheet

U support connector FT

Item number: 6018378



Dimensions

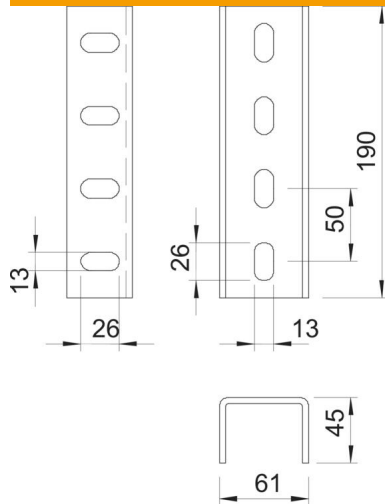

Dimension	45 x 61 x 190
Length	190 mm
Width	61 mm
Height	45 mm

Technical data

Type of perforation	3 sides perforated
Version for	Internal connector
Drill hole spacing, centre	50 mm
Suitable for profile shapes	U profile
Hole size	13 x 26 mm
Material thickness	4 mm
With screw accessories	yes
Profile shape	U profile
Rustproof steel, pickled	no