


# Technical data sheet

## Cover for DD mounting/branch piece

Item number: 6231938



Cover for wide span add-on tee with pre-mounted turn buckles.

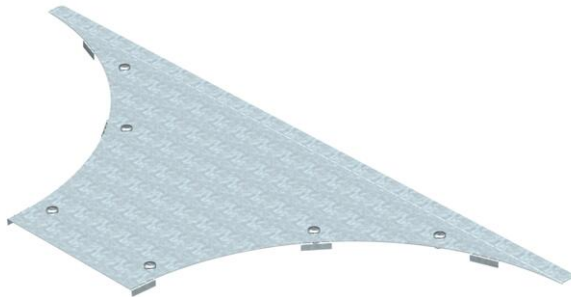


**St** Steel

**DD** Strip galvanised zinc/aluminium, Double Dip

### Master data

|                     |                                             |
|---------------------|---------------------------------------------|
| Item number         | 6231938                                     |
| Type                | WAAD 600 DD                                 |
| Description 1       | Cover, add-on tee                           |
| Description 2       | wide span system 110 and 160                |
| Manufacturer        | OBO                                         |
| Dimension           | B600mm                                      |
| Colour              | zinc                                        |
| Material            | Steel                                       |
| Surface             | Strip galvanised zinc/aluminium, Double Dip |
| Surface standard    | DIN EN 10346                                |
| Smallest sales unit | 1                                           |
| Unit of quantity    | Piece                                       |
| Weight              | 552.1 kg                                    |
| Weight unit         | kg/100 pc.                                  |

### Dimensions

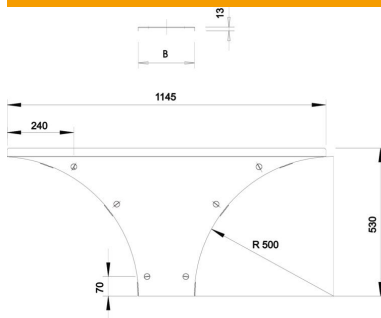

|                 |        |
|-----------------|--------|
| Width           | 600 mm |
| Height          | 110 mm |
| Plate thickness | 1.5 mm |
| Dimension B     | 600 mm |
| Dimension H     | 15 mm  |
| Dimension R     | 500 mm |

# Technical data sheet

Cover for DD mounting/branch piece

Item number: 6231938



## Technical data

|                           |           |
|---------------------------|-----------|
| Number of turn buckles    | 6 St.     |
| Fastening type            | Sash lock |
| Suitable for cable ladder | yes       |
| Suitable for cable tray   | yes       |
| Material thickness        | 1.5 mm    |
| Rustproof steel, pickled  | no        |
| Wide-span version         | yes       |