

Technical data sheet

End piece, trunking type WDKH 20020

Item number: 6175928



End piece for closing the WDK-H trunking.



Polycarbonate/Acrylnitrile-butadiene-styrene

Master data	
Item number	6175928
Type	WDKH-E20020LGR
Description 1	End piece
Description 2	halogen-free
Manufacturer	OBO
Dimension	20x20mm
Colour	Light grey; RAL 7035
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.089 kg
Weight unit	kg/100 pc.


Technical data sheet

End piece, trunking type WDKH 20020

Item number: 6175928



Dimensions

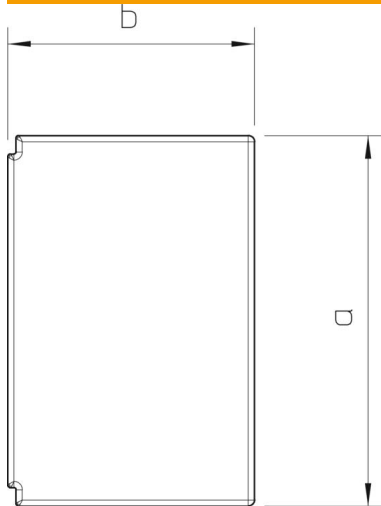

Length	11.5 mm
Width	17 mm
Height	17 mm
Dimension a	19 mm
Dimension b	18 mm

Technical data

Version for	Left/right
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	yes
Protection rating	IP30
Protective film	no
Protection rating IK code	IK07.
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C