


Technical data sheet

End piece, trunking type WDKH 30045

Item number: 6175554

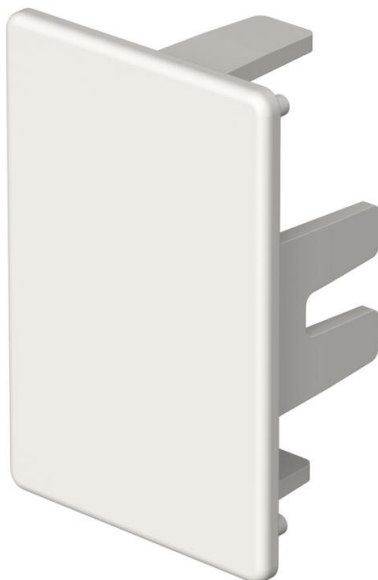

End piece for closing the WDK-H trunking.



Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6175554
Type	WDKH-E30045RW
Description 1	End piece
Description 2	halogen-free
Manufacturer	OBO
Dimension	30x45mm
Colour	Pure white; RAL 9010
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.435 kg
Weight unit	kg/100 pc.

Technical data sheet

End piece, trunking type WDKH 30045

Item number: 6175554



Dimensions



Length	17 mm
Width	45 mm
Height	30 mm
Dimension a	45 mm
Dimension b	30 mm

Technical data

Version for	Left/right
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	yes
Protection rating	IP30
Protective film	no
Protection rating IK code	IK07.
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C