

Technical data sheet

End piece, trunking type WDKH 60110

Item number: 6175566



End piece for closing the WDK-H trunking.



Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6175566
Type	WDKH-E60110RW
Description 1	End piece
Description 2	halogen-free
Manufacturer	OBO
Dimension	60x110mm
Colour	Pure white; RAL 9010
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	10
Unit of quantity	Piece
Weight	2.556 kg
Weight unit	kg/100 pc.


Technical data sheet

End piece, trunking type WDKH 60110

Item number: 6175566



Dimensions

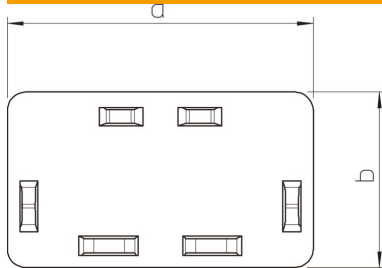

Length	27.5 mm
Width	110 mm
Height	60 mm
Dimension a	110 mm
Dimension b	60 mm

Technical data

Version for	Left/right
Fastening type	Lockable
Halogen-free	yes
Protection rating	IP30
Protective film	no
Protection rating IK code	IK07.
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C