

# Technical data sheet

## T and intersection cover, for trunking type WDKH 60150

Item number: 6176092



T and intersection cover for changing the direction of the halogen-free WDKH trunking. The fitting is preperforated at the side for the connection of different trunking cross-sections.



PC/  
ABS

Polycarbonate/Acrylnitrile-butadiene-styrene

### Master data

|                                    |                                              |
|------------------------------------|----------------------------------------------|
| Item number                        | 6176092                                      |
| Type                               | WDKH-T60150LGR                               |
| Description 1                      | T- and crosspiece cover                      |
| Description 2                      | halogen-free                                 |
| Manufacturer                       | OBO                                          |
| Dimension                          | 60x150mm                                     |
| Colour                             | Light grey; RAL 7035                         |
| Material                           | Polycarbonate/Acrylnitrile-butadiene-styrene |
| Smallest sales unit                | 2                                            |
| Unit of quantity                   | Piece                                        |
| Weight                             | 23.463 kg                                    |
| Weight unit                        | kg/100 pc.                                   |
| CO2 Footprint (GWP) Cradle-to-Gate | 1,2606 kg CO2e / 1 Piece                     |


# Technical data sheet

T and intersection cover, for trunking type WDKH 60150

Item number: 6176092



## Dimensions

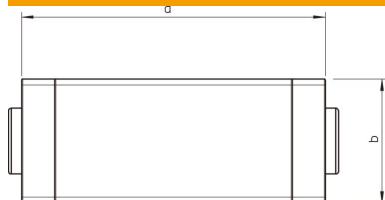

|             |        |
|-------------|--------|
| Length      | 291 mm |
| Width       | 150 mm |
| Height      | 60 mm  |
| Dimension a | 291 mm |
| Dimension b | 155 mm |

## Technical data

|                                                  |              |
|--------------------------------------------------|--------------|
| Version for                                      | Hood fitting |
| Fastening type                                   | Lockable     |
| Maintain electrical functions for duct dimension | no<br>60x    |
| Halogen-free                                     | yes          |
| Trunking depth                                   | 60 mm        |
| Protection rating                                | IP30         |
| Protective film                                  | no           |
| Protection rating IK code                        | IK07.        |
| Permitted temperature range, max.                | 90 °C        |
| Permitted temperature range, min.                | -5 °C        |