

Technical data sheet

Flat angle, trunking type WDK 80210

Item number: 6192107



Flat angle for changing the direction of the WDK trunking.



PVC Polyvinylchloride

Master data

Item number	6192107
Description 1	Flat angle
Manufacturer	OBO
Dimension	560,5x210x80
Colour	Stone grey; RAL 7030
Material	Polyvinylchloride
Smallest sales unit	1
Unit of quantity	Piece
Weight	220 kg
Weight unit	kg/100 pc.


Technical data sheet

Flat angle, trunking type WDK 80210

Item number: 6192107



Dimensions

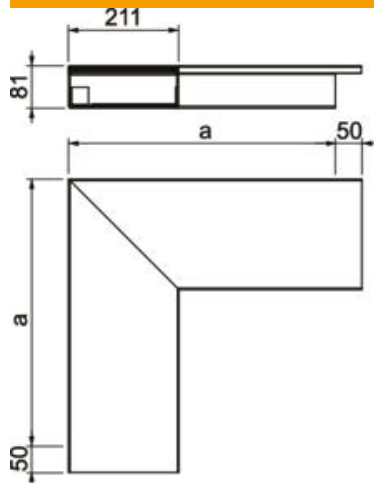

Length	560 mm
Width	210 mm
Height	80 mm
Dimension a	560.5 mm

Technical data

Version for	Base and cover
Fastening type	Base perforation
Maintain electrical functions	no
for duct dimension	80 x 210
Halogen-free	no
Trunking depth	80 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm