


Technical data sheet

External corner cover, trunking type WDK 60130

Item number: 6022162



External corner hood for changing the direction of the WDK trunking.

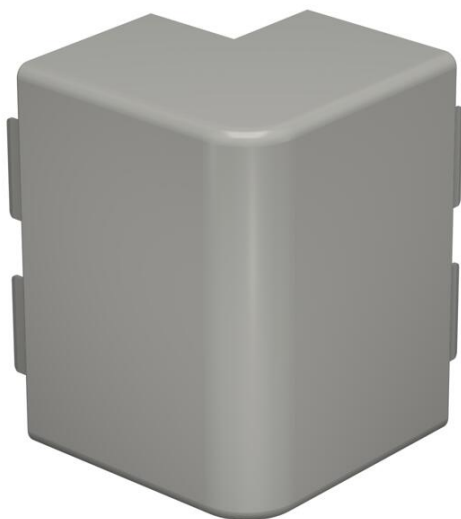

PVC Polyvinylchloride

Master data

Item number	6022162
Type	WDK HA60130GR
Description 1	External corner hood
Manufacturer	OBO
Dimension	60x130mm
Colour	Stone grey; RAL 7030
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Piece
Weight	14.327 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,3761 kg CO2e / 1 Piece


Technical data sheet

External corner cover, trunking type WDK 60130

Item number: 6022162



Dimensions

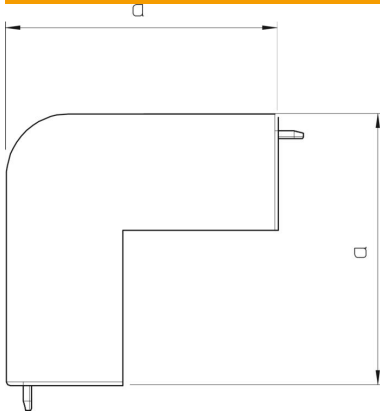

Length	100 mm
Width	130 mm
Height	60 mm
Dimension a	100 mm
Dimension H	130 mm

Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	60 x 130
Halogen-free	no
Trunking depth	60 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Self-extinguishing	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm