


# Technical data sheet

## End piece, trunking type WDK 100130

Item number: 6163041

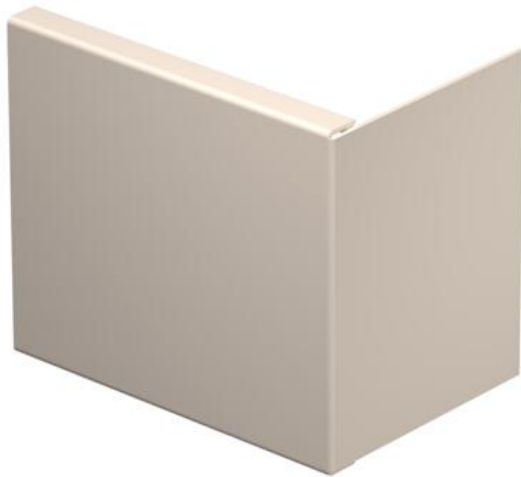

End piece to close the WDK trunking.  
The end pieces are pushed onto the WDK trunking in the same way as the covers.




**PVC** Polyvinylchloride

### Master data

|                     |                   |
|---------------------|-------------------|
| Item number         | 6163041           |
| Description 1       | End piece         |
| Manufacturer        | OBO               |
| Dimension           | 100x130mm         |
| Colour              | Cream; RAL 9001   |
| Material            | Polyvinylchloride |
| Smallest sales unit | 10                |
| Unit of quantity    | Piece             |
| Weight              | 8.2 kg            |
| Weight unit         | kg/100 pc.        |

### Dimensions

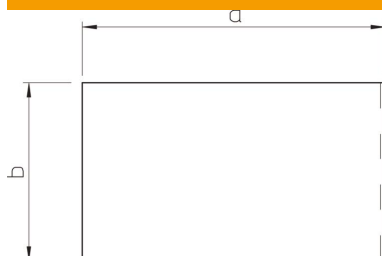

|             |        |
|-------------|--------|
| Length      | 150 mm |
| Width       | 130 mm |
| Height      | 100 mm |
| Dimension a | 150 mm |
| Dimension b | 130 mm |
| Dimension H | 130 mm |

# Technical data sheet

End piece, trunking type WDK 100130

Item number: 6163041



## Technical data

|                                   |            |
|-----------------------------------|------------|
| Version for                       | Left/right |
| Fastening type                    | Lockable   |
| Maintain electrical functions     | no         |
| Halogen-free                      | no         |
| Protection rating                 | IP30       |
| Protective film                   | no         |
| Protection rating IK code         | IK04       |
| Permitted temperature range, max. | 60 °C      |
| Permitted temperature range, min. | -5 °C      |