


# Technical data sheet

## End piece, trunking type WDK 100130

Item number: 6024882

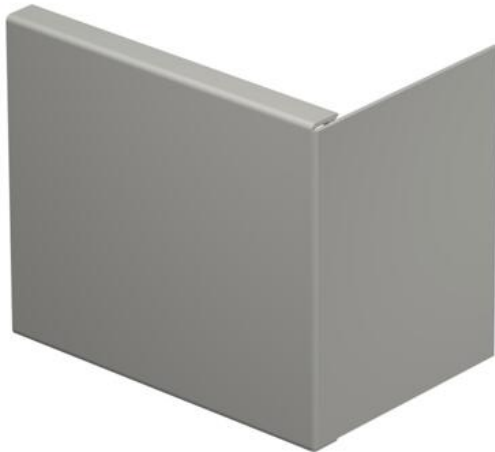

End piece to close the WDK trunking.  
The end pieces are pushed onto the WDK trunking in the same way as the covers.




**PVC** Polyvinylchloride

### Master data

|                     |                      |
|---------------------|----------------------|
| Item number         | 6024882              |
| Description 1       | End piece            |
| Manufacturer        | OBO                  |
| Dimension           | 100x130mm            |
| Colour              | Stone grey; RAL 7030 |
| Material            | Polyvinylchloride    |
| Smallest sales unit | 10                   |
| Unit of quantity    | Piece                |
| Weight              | 8.2 kg               |
| Weight unit         | kg/100 pc.           |

### Dimensions

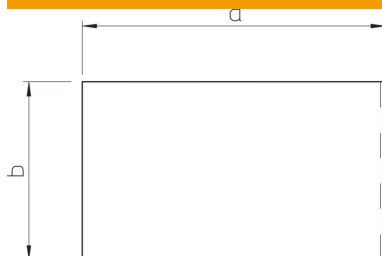

|             |        |
|-------------|--------|
| Length      | 150 mm |
| Width       | 130 mm |
| Height      | 100 mm |
| Dimension a | 150 mm |
| Dimension b | 130 mm |
| Dimension H | 130 mm |

# Technical data sheet

End piece, trunking type WDK 100130

Item number: 6024882



## Technical data

|                                   |            |
|-----------------------------------|------------|
| Version for                       | Left/right |
| Fastening type                    | Lockable   |
| Maintain electrical functions     | no         |
| Halogen-free                      | no         |
| Protection rating                 | IP30       |
| Protective film                   | no         |
| Protection rating IK code         | IK04       |
| Permitted temperature range, max. | 60 °C      |
| Permitted temperature range, min. | -5 °C      |