


Technical data sheet

End piece, trunking type WDK 10020

Item number: 6153593

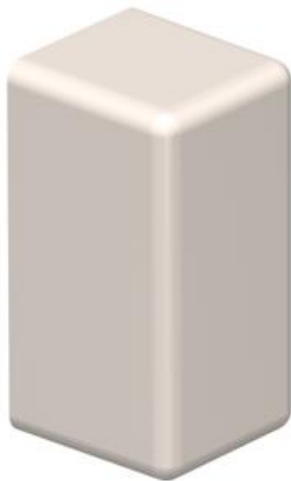

End piece for closing the WDK trunking.
The end pieces are pushed onto the WDK trunking and are fixed on the floor connector by spring force.



PVC

 Polyvinylchloride

Master data		
Item number		6153593
Type		WDK HE10020CW
Description 1		End piece
Manufacturer		OBO
Dimension		10x20mm
Colour		Cream; RAL 9001
Material		Polyvinylchloride
Smallest sales unit		10
Unit of quantity		Piece
Weight		0.106 kg
Weight unit		kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate		0,0061 kg CO2e / 1 Piece


Technical data sheet

End piece, trunking type WDK 10020

Item number: 6153593



Dimensions

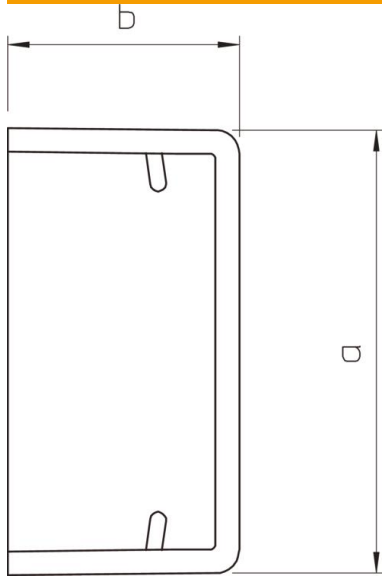

Length	11 mm
Width	22 mm
Height	10 mm
Dimension a	22 mm
Dimension b	11 mm
Dimension H	20 mm

Technical data

Version for	Left/right
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C