

Technical data sheet

End piece, trunking type WDK 10020

Item number: 6154514



End piece for closing the WDK trunking.
The end pieces are pushed onto the WDK trunking and are fixed on the floor connector by spring force.



PVC Polyvinylchloride

Master data

Item number	6154514
Description 1	End piece
Manufacturer	OBO
Dimension	10x20mm
Colour	Pure white; RAL 9010
Material	Polyvinylchloride
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.106 kg
Weight unit	kg/100 pc.


Technical data sheet

End piece, trunking type WDK 10020

Item number: 6154514



Dimensions

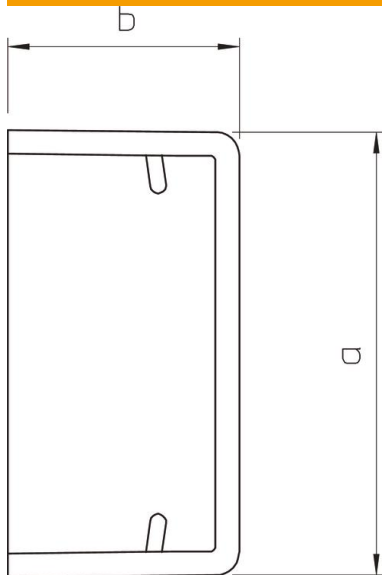

Length	11 mm
Width	22 mm
Height	10 mm
Dimension a	22 mm
Dimension b	11 mm
Dimension H	20 mm

Technical data

Version for	Left/right
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C