

Technical data sheet

End piece, trunking type WDK 100230

Item number: 6193399



End piece to close the WDK trunking.
The end pieces are pushed onto the WDK trunking and are fixed on the floor connector by spring force.



PVC

 Polyvinylchloride

Master data		
Item number	6193399	
Type	WDK HE100230RW	
Description 1	End piece	
Manufacturer	OBO	
Dimension	100x230mm	
Colour	Pure white; RAL 9010	
Material	Polyvinylchloride	
Smallest sales unit	5	
Unit of quantity	Piece	
Weight	10.409 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,2547 kg CO2e / 1 Piece	


Technical data sheet

End piece, trunking type WDK 100230

Item number: 6193399



Dimensions

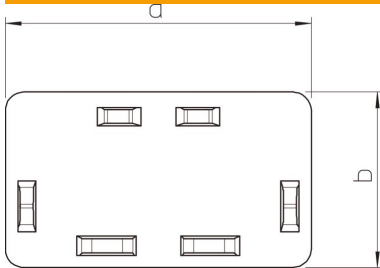

Length	25 mm
Width	230 mm
Height	100 mm
Dimension a	230 mm
Dimension b	100 mm
Dimension H	230 mm

Technical data

Version for	Left/right
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C