

Technical data sheet

End piece, Trunking type WDK 10030

Item number: 6153607



End piece to close the WDK trunking.
The end pieces are pushed onto the WDK trunking and are fixed on the floor connector by spring force.



PVC

 Polyvinylchloride

Master data	
Item number	6153607
Description 1	End piece
Manufacturer	OBO
Dimension	10x30mm
Colour	Cream; RAL 9001
Material	Polyvinylchloride
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.139 kg
Weight unit	kg/100 pc.


Technical data sheet

End piece, Trunking type WDK 10030

Item number: 6153607



Dimensions

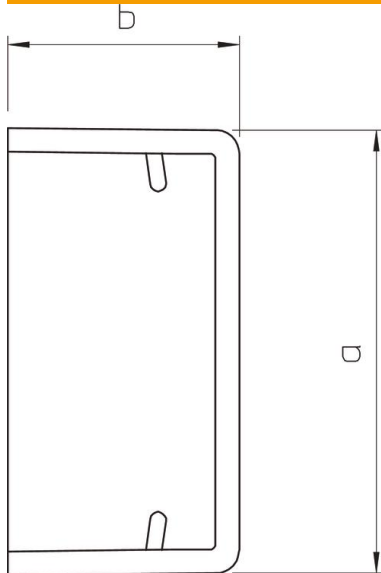

Length	11 mm
Width	32 mm
Height	10 mm
Dimension a	32 mm
Dimension b	11 mm
Dimension H	30 mm

Technical data

Version for	Left/right
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C