

Technical data sheet

End piece, trunking type WDK 15015

Item number: 6193099



End piece to close the WDK trunking.

The end pieces are pushed onto the WDK trunking and are fixed on the floor connector by spring force.




PVC Polyvinylchloride

Master data

Item number	6193099
Description 1	End piece
Manufacturer	OBO
Dimension	15x15mm
Colour	Pure white; RAL 9010
Material	Polyvinylchloride
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.082 kg
Weight unit	kg/100 pc.

Dimensions

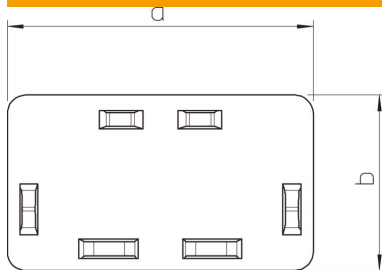

Length	11.5 mm
Width	15 mm
Height	15 mm
Dimension a	15 mm
Dimension b	15 mm
Dimension H	15 mm

Technical data sheet

End piece, trunking type WDK 15015

Item number: 6193099



Technical data

Version for	Left/right
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C