


Technical data sheet

End piece, trunking type WDK 15015

Item number: 6193420

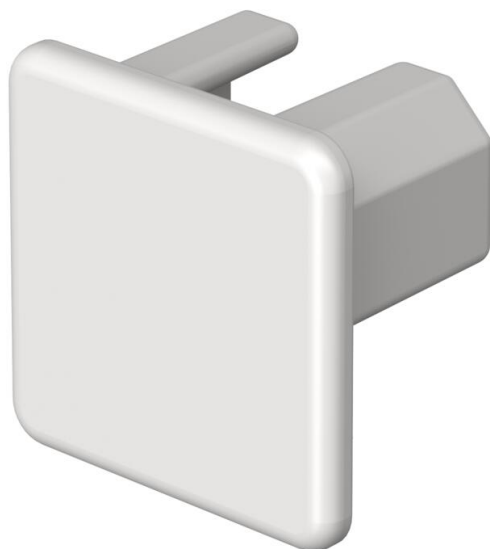

End piece to close the WDK trunking.
The end pieces are pushed onto the WDK trunking and are fixed on the floor connector by spring force.



PVC Polyvinylchloride

Master data

Item number	6193420
Type	WDK HE15015VW
Description 1	End piece
Manufacturer	OBO
Dimension	15x15mm
Colour	Traffic white; RAL 9016
Material	Polyvinylchloride
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.082 kg
Weight unit	kg/100 pc.


Technical data sheet

End piece, trunking type WDK 15015

Item number: 6193420



Dimensions

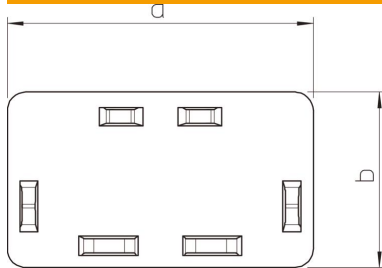

Length	11.5 mm
Width	15 mm
Height	15 mm
Dimension a	15 mm
Dimension b	15 mm
Dimension H	15 mm

Technical data

Version for	Left/right
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C