


# Technical data sheet

## End piece, trunking type WDK 30045

Item number: 6162584

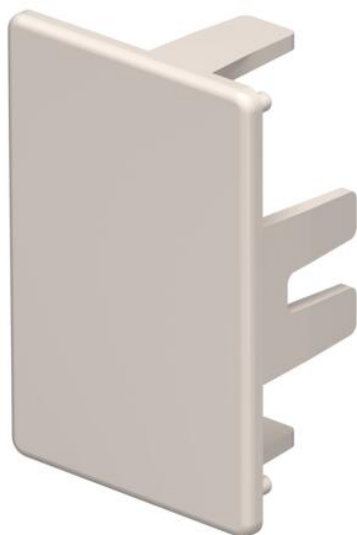

End piece to close the WDK trunking.  
The end pieces are pushed onto the WDK trunking and are fixed on the floor connector by spring force.



**PVC** Polyvinylchloride

### Master data

|                     |                   |
|---------------------|-------------------|
| Item number         | 6162584           |
| Type                | WDK HE30045CW     |
| Description 1       | End piece         |
| Manufacturer        | OBO               |
| Dimension           | 30x45mm           |
| Colour              | Cream; RAL 9001   |
| Material            | Polyvinylchloride |
| Smallest sales unit | 10                |
| Unit of quantity    | Piece             |
| Weight              | 0.509 kg          |
| Weight unit         | kg/100 pc.        |


# Technical data sheet

End piece, trunking type WDK 30045

Item number: 6162584



## Dimensions

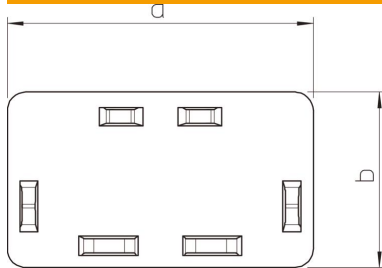

|             |       |
|-------------|-------|
| Length      | 17 mm |
| Width       | 45 mm |
| Height      | 30 mm |
| Dimension a | 45 mm |
| Dimension b | 30 mm |
| Dimension H | 45 mm |

## Technical data

|                                   |            |
|-----------------------------------|------------|
| Version for                       | Left/right |
| Fastening type                    | Lockable   |
| Maintain electrical functions     | no         |
| Halogen-free                      | no         |
| Protection rating                 | IP30       |
| Protective film                   | no         |
| Protection rating IK code         | IK04       |
| Permitted temperature range, max. | 60 °C      |
| Permitted temperature range, min. | -5 °C      |