


Technical data sheet

End piece, trunking type WDK 40040

Item number: 6193218



End piece to close the WDK trunking.
The end pieces are pushed onto the trunking and kept in place by the spring action.

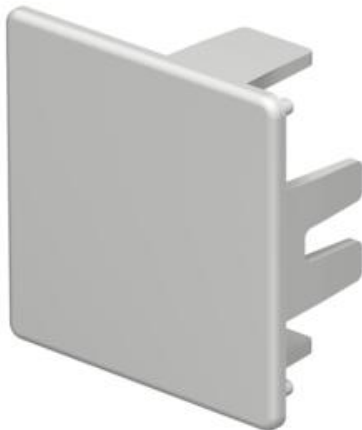

PVC Polyvinylchloride

Master data	
Item number	6193218
Description 1	End piece
Manufacturer	OBO
Dimension	40x40mm
Colour	Pure white; RAL 9010
Material	Polyvinylchloride
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.602 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	2,2617 kg COe / 1 Piece

Technical data sheet

End piece, trunking type WDK 40040

Item number: 6193218



Dimensions



Length	17 mm
Width	40 mm
Height	40 mm
Dimension a	40 mm
Dimension b	40 mm
Dimension H	40 mm

Technical data

Version for	Left/right
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C