

# Technical data sheet

End piece, trunking type WDK 40060

Item number: 6193444



End piece to close the WDK trunking.  
The end pieces are pushed onto the trunking and kept in place by the spring action.



**PVC** Polyvinylchloride

## Master data

|                     |                         |
|---------------------|-------------------------|
| Item number         | 6193444                 |
| Type                | WDK HE40060VW           |
| Description 1       | End piece               |
| Manufacturer        | OBO                     |
| Dimension           | 40x60mm                 |
| Colour              | Traffic white; RAL 9016 |
| Material            | Polyvinylchloride       |
| Smallest sales unit | 10                      |
| Unit of quantity    | Piece                   |
| Weight              | 1.136 kg                |
| Weight unit         | kg/100 pc.              |


# Technical data sheet

End piece, trunking type WDK 40060

Item number: 6193444



## Dimensions

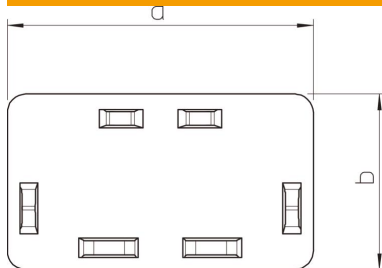

|             |         |
|-------------|---------|
| Length      | 27.5 mm |
| Width       | 60 mm   |
| Height      | 40 mm   |
| Dimension a | 60 mm   |
| Dimension b | 40 mm   |
| Dimension H | 60 mm   |

## Technical data

|                                   |            |
|-----------------------------------|------------|
| Version for                       | Left/right |
| Fastening type                    | Lockable   |
| Maintain electrical functions     | no         |
| Halogen-free                      | no         |
| Protection rating                 | IP30       |
| Protective film                   | no         |
| Protection rating IK code         | IK04       |
| Permitted temperature range, max. | 60 °C      |
| Permitted temperature range, min. | -5 °C      |