

Technical data sheet

End piece, trunking type WDK 60110

Item number: 6193456



End piece for closing the WDK trunking.
The end pieces are pushed onto the trunking and kept in place by the spring action.



PVC Polyvinylchloride

Master data

Item number	6193456
Type	WDK HE60110VW
Description 1	End piece
Manufacturer	OBO
Dimension	60x110mm
Colour	Traffic white; RAL 9016
Material	Polyvinylchloride
Smallest sales unit	10
Unit of quantity	Piece
Weight	2.937 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1064 kg CO2e / 1 Piece


Technical data sheet

End piece, trunking type WDK 60110

Item number: 6193456



Dimensions

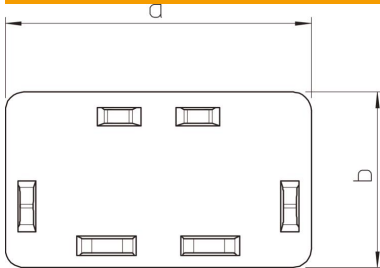

Length	27.5 mm
Width	110 mm
Height	60 mm
Dimension a	110 mm
Dimension b	60 mm
Dimension H	110 mm

Technical data

Version for	Left/right
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C