

Technical data sheet

End piece, for trunking type WDK 60170

Item number: 6022545



End piece to close the WDK trunking.  
The end pieces are pushed onto the trunking and kept in place by the spring action.



**PVC** Polyvinylchloride

| Master data         |                      |
|---------------------|----------------------|
| Item number         | 6022545              |
| Description 1       | End piece            |
| Manufacturer        | OBO                  |
| Dimension           | 60x170mm             |
| Colour              | Stone grey; RAL 7030 |
| Material            | Polyvinylchloride    |
| Smallest sales unit | 10                   |
| Unit of quantity    | Piece                |
| Weight              | 4.859 kg             |
| Weight unit         | kg/100 pc.           |


# Technical data sheet

End piece, for trunking type WDK 60170

Item number: 6022545



## Dimensions

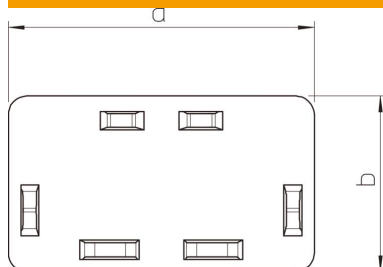

|             |         |
|-------------|---------|
| Length      | 27.5 mm |
| Width       | 170 mm  |
| Height      | 60 mm   |
| Dimension a | 170 mm  |
| Dimension b | 60 mm   |
| Dimension H | 170 mm  |

## Technical data

|                                   |            |
|-----------------------------------|------------|
| Version for                       | Left/right |
| Fastening type                    | Lockable   |
| Maintain electrical functions     | no         |
| Halogen-free                      | no         |
| Protection rating                 | IP30       |
| Protective film                   | no         |
| Protection rating IK code         | IK04       |
| Permitted temperature range, max. | 60 °C      |
| Permitted temperature range, min. | -5 °C      |