

Technical data sheet

Flat angle hood, for trunking type WDK 10020

Item number: 6152600



Flat angle hood for changing the direction of the WDK trunking.



PVC Polyvinylchloride

Master data

Item number	6152600
Type	WDK HF10020CW
Description 1	Flat angle cover
Manufacturer	OBO
Dimension	10x20mm
Colour	Cream; RAL 9001
Material	Polyvinylchloride
Smallest sales unit	4
Unit of quantity	Piece
Weight	0.365 kg
Weight unit	kg/100 pc.


Technical data sheet

Flat angle hood, for trunking type WDK 10020

Item number: 6152600



Dimensions

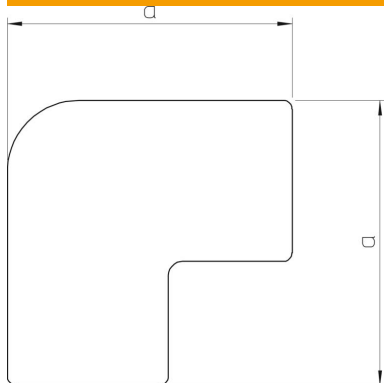

Length	40 mm
Width	22 mm
Height	10 mm
Dimension a	40 mm
Dimension H	20 mm

Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	10 x 20
Halogen-free	no
Trunking depth	10 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm