

Technical data sheet

Flat angle cover, trunking type WDK 10030

Item number: 6152619



Flat angle hood for changing the direction of the WDK trunking.



PVC Polyvinylchloride

Master data

Item number	6152619
Type	WDK HF10030CW
Description 1	Flat angle cover
Manufacturer	OBO
Dimension	10x30mm
Colour	Cream; RAL 9001
Material	Polyvinylchloride
Smallest sales unit	4
Unit of quantity	Piece
Weight	0.555 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0202 kg CO2e / 1 Piece


Technical data sheet

Flat angle cover, trunking type WDK 10030

Item number: 6152619



Dimensions

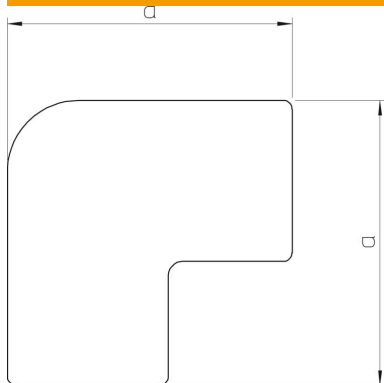

Length	50 mm
Width	30 mm
Height	10 mm
Dimension a	50 mm
Dimension H	30 mm

Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	10 x 30
Halogen-free	no
Trunking depth	10 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm