

Technical data sheet

Flat angle cover, trunking type WDK 20050

Item number: 6152686



Flat angle hood for changing the direction of the WDK trunking.



PVC

 Polyvinylchloride

Master data	
Item number	6152686
Description 1	Flat angle cover
Manufacturer	OBO
Dimension	20x50mm
Colour	Cream; RAL 9001
Material	Polyvinylchloride
Smallest sales unit	4
Unit of quantity	Piece
Weight	1.948 kg
Weight unit	kg/100 pc.


Technical data sheet

Flat angle cover, trunking type WDK 20050

Item number: 6152686



Dimensions

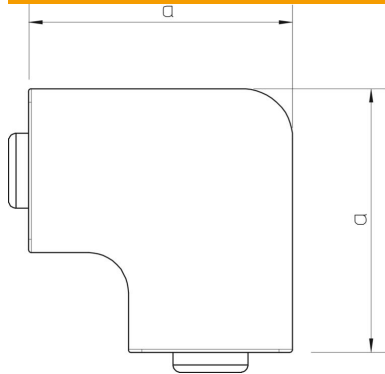

Length	73 mm
Width	50 mm
Height	20 mm
Dimension a	73 mm
Dimension H	50 mm

Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	20 x 50
Halogen-free	no
Trunking depth	20 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm