

Technical data sheet

Flat angle cover, trunking type WDK 25040

Item number: 6158625



Flat angle hood for changing the direction of the WDK trunking.



PVC Polyvinylchloride

Master data

Item number	6158625
Type	WDK HF25040GR
Description 1	Flat angle cover
Manufacturer	OBO
Dimension	25x40mm
Colour	Stone grey; RAL 7030
Material	Polyvinylchloride
Smallest sales unit	4
Unit of quantity	Piece
Weight	1.905 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0556 kg CO2e / 1 Piece


Technical data sheet

Flat angle cover, trunking type WDK 25040

Item number: 6158625



Dimensions

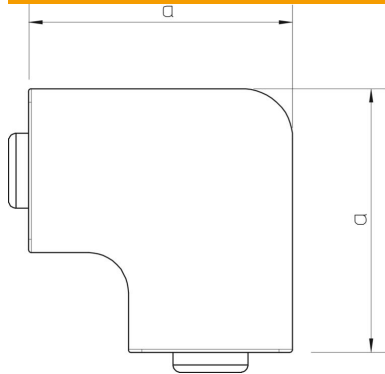

Length	63 mm
Width	40 mm
Height	25 mm
Dimension a	63 mm
Dimension H	40 mm

Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	25 x 40
Halogen-free	no
Trunking depth	25 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm